

Hubbell Has Your Electrical Solutions...



YOUR ONE STOP SOURCE FOR "INDUSTRIAL MRO" NEEDS!

- Downtime Reduction
- Increased Productivity
- Personal Safety
- Healthy Environment



Panel Safe — Arc Flash Solution (Page 398 - Catalog 399)


Description	Hubbell #	Grainger#
20A 125V GFCI with In-Cabinet receptacle	PR20	1CXG9
20A 125V GFCI with In-Cabinet receptacle & Cat 5e Ethernet Access	PR205E	1CXG2
20A 125V GFCI with In-Cabinet receptacle & Cat 5e Ethernet Access NEMA 4X	PR4X205E	1CXG7
15A 125V Power and Cat 5e Ethernet Access	PR155E	1CXF8



1CXG2

MotorQuick™ — Quick Motor Changeouts (Page 529 - Catalog 399)

Description	Hubbell #	Grainger#
Switched Enclosure, NEMA 4X Receptacle, Female	HBLDS3MQR	2XE18
Switched Enclosure, NEMA 4X Corderd, 10/4 5-Ft.	HBLDS3MQ5	2XE19
Male Inlet, 10/4 1-Ft. Leads	RM3004PA001	2XE20
Double End Cable, Male/Female, 10/4 5-Ft.	RM3004PA005	2XE21

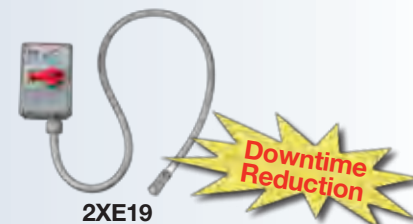

2XE19

Watertight Safety-Shroud™ Twist-Lock® Plugs & Connectors (Page 528 - Catalog 399)

Description	Plugs		Connectors	
	Hubbell #	Grainger #	Hubbell #	Grainger#
20 Amp, 2P 3W 125V	HBL2311SW	4CT65	HBL2313SW	4CT66
20 Amp, 2P 3W 250V	HBL2321SW	4CT73	HBL2323SW	4CT74
30 Amp, 2P 3W 125V	HBL2611SW	4CV21	HBL2613SW	4CV22
30 Amp, 2P 3W 250V	HBL2621SW	4CV29	HBL2623SW	4CV30
30 Amp, 3P 4W 125/250V	HBL2711SW	4CV37	HBL2713SW	4CV38
30 Amp, 3P 4W 250V	HBL2721SW	4CV45	HBL2723SW	4CV46
30 Amp, 3P 4W 480V	HBL2731SW	4CV53	HBL2733SW	4CV54



4CV29



4CV30

TrukTrak®/TredTrak® — Eliminate Trip Hazards (Page 429 - Catalog 399)

Description	Hubbell #	Grainger #
TrukTrak (20,150-Pound Max. Load)		
5 Channel 3 Ft. (L)	HBLTT5B	4CV89
5 Channel End Caps (pair)	HBLTT5ECB	4CV92
3 Channel 3 Ft. (L)	HBLTT3B	4CV85
3 Channel End Caps (pair)	HBLTT3ECB	4CV88
TredTrak (10,500-Pound Max. Load)		
5 Channel 3 Ft. (L)	HBLTRED5B	4HD47
5 Channel End Caps (pair)	HBLTRED5ECB	4HD48



4H047

Circuit-Lock® Safety Switched Enclosures NEMA Type 4X (Page 529 - Catalog 399)

Description, Unfused	Hubbell #	Grainger #	Description, Fused	Hubbell #	Grainger #
30 Amp, 600V	HBLDS3	3D383	30 Amp, 600V	FDS30	3D340
60 Amp, 600V	HBLDS6	4CV74	60 Amp, 600V	FDS60	3D341
100 Amp, 600V	HBLDS10AC	4CV73			



3D383

PLUGOUT®/SWITCHOUT™ Lockout Devices (Page 519 - Catalog 525)

Description	Hubbell #	Grainger #
To accept 15/20 Amp molded plugs	HLDMP	3D384
To accept 20/30 Amp plugs	HLD	6C647
To accept standard toggle switches	HSLD	3D385



6C647

Hubbell Has Your Electrical Solutions...



YOUR ONE STOP SOURCE FOR "HEALTHCARE" NEEDS!

- Personal Safety
- Energy Savings (Green)
- Safe & Secure Environment
- Healthy Environment



Tamper Resistant Hospital Grade Receptacles (Page 515 - Catalog 399)

15 Amp 125 Volt Duplex Description	Hubbell #	Grainger#
Heavy Duty Brown	HBL8200SGA	6C656
Heavy Duty Ivory	HBL8200SGIA	5Z829
Heavy Duty Red	HBL8200SGRA	4D038
20 Amp 125 Volt Duplex Description	Hubbell #	Grainger#
Heavy Duty Brown	HBL8300SGA	4CV77
Heavy Duty Ivory	HBL8300SGIA	4CV79
Heavy Duty Red	HBL8300SGRA	4CV80

GFCI Hospital Grade Receptacles — Personnel Protection (Page 515 - Catalog 399)

15 Amp 125 Volt Duplex Description	Hubbell #	Grainger#
Heavy Duty Brown	GFR8200TR	1GBX6
General Duty Brown	GFR8200HL	2XB86
20 Amp 125 Volt Duplex Description	Hubbell #	Grainger#
Heavy Duty Brown	GFR8300TR	1GBY9
General Duty Brown	GFR8300HL	2XB89
Description	Hubbell #	Grainger#
GFCI Tester	GFT-2G	3D360

Tester measures milliamp (mA) trip levels of breakers, receptacles & wired in GFCI's within any range from 2- 7 mA.

GFCI Plugs — Safety Plugs for Electrical Tools (Page 393 - Catalog 399)

15 Amp 125 Volt Manual Reset Description	Hubbell #	Grainger#
Black Plug	GFP5266C	4HD20
Yellow Plug	GFP5266CY	4HD21
Yellow Plug w/1 foot cord	GFP1C	4HD19

15A Hospital Grade Plugs & Connectors (Page 511 - Catalog 399)

Description	Hubbell #	Grainger#
Heavy Duty Insulgrip Plug	HBL8215C	5A076
Heavy Duty Insulgrip Clear Angle Plug	HBL8215CAT	5Z869
General Duty Valise Plug White	HBL8115V	5Z871
Heavy Duty Insulgrip Connector	HBL8219C	5A077
General Duty Valise Connector White	HBL8119V	5Z874

Motion Sensors — Energy Savings (Page 599- Catalog 399)

Wall Switch Sensors Description	Hubbell #	Grainger#
Passive Infrared, 1200 Sq. Ft. Coverage, 120/277 Volts	WS1277I	1VD96
Ultrasonic, 400 Sq. Ft. Coverage, 120/277 Volts	AU1277I1N	1MEA3
Dual Technology, 1000 Sq. Ft. Coverage 120/277 Volts	AD1277I1	1MEA9
Ceiling Mount Sensors Description	Hubbell #	Grainger#
Dual Technology, 2000 Sq. Ft. Coverage	ATD2000C	1ND52
Dual Technology, 1000 Sq. Ft. Coverage	ATD1000C	1ND50
Ultrasonic Technology, 2000 Sq. Ft. Coverage	ATU2000C	1ND82

See Grainger Catalog or Website for Additional Configurations and Colors



4CV77



 
3AU63



3D360



4HD21



5A076



1MEA9



1ND52

Hubbell Has Your Electrical Solutions...



YOUR ONE STOP SOURCE FOR "GOVERNMENT" NEEDS!

- Energy Savings (Green)
- Increased Productivity
- Safe & Secure Environment
- Healthy Environment
- Emergency Preparedness



Motion Sensors – Energy Savings

(Page 599 - Catalog 399)

Wall Switch Sensors Description	Hubbell #	Grainger#
Passive Infrared, 1200 Sq. Ft. Coverage, 120/277 Volts	WS1277I	1VD96
Ultrasonic, 400 Sq. Ft. Coverage, 120/277 Volts	AU127711N	1MEA3
Dual Technology, 1000 Sq. Ft. Coverage 120/277 Volts	AD127711	1MEA9
Ceiling Mount Sensors Description	Hubbell #	Grainger#
Dual Technology, 2000 Sq. Ft. Coverage	ATD2000C	1ND52
Dual Technology, 1000 Sq. Ft. Coverage	ATD1000C	1ND50
Ultrasonic Technology, 2000 Sq. Ft. Coverage	ATU2000C	1ND82

See Grainger Catalog or Website for Additional Configurations and Colors



IMEA9



IND52



1RZB7



1MBK6

Raceway

(Page 491- Catalog 399)

Metal Racway Description	Hubbell #	Grainger#
HBL500 Series Raceway, Single Channel, 10 Ft.	HBL50010IV	1RZB7
HBL750 Series Raceway, Single Channel, 10Ft.	HBL75010IV	1RZB8
HBL500 and HBL750 Series Raceway, Switch and Receptacle Box, One Gang	HBL5748IV	1RYV3
Metal PlugTrak, 5 Ft., 5 Outlets, 12" Centers, Ivory	HBL20GB512IV	1MBX6
Non-Metallic Raceway Description	Hubbell #	Grainger#
PremiseTrak, Single Channel, Adhesive, Base and Cover	PP1ABC7	1MBP6
BaseTrak, 3 channel, Base and Cover	PB3BC10	1MBK6
PremiseTrak Standard Box 1 Gang	PDB12S	1MBL9
BaseTrak, Full Capacity Box, 1 Gang, Raised box	PB3GCIB	1MBL1

See Grainger Catalog or Website for Additional Configurations



2XB81



4HD21

Ground Fault Protection – Personnel Protection

(Page 515 - Catalog 399)

Description	Hubbell #	Grainger#
15A 125V, LED GFCI Receptacle, Ivory	GF15IL	2XB81
20A 125V, LED GFCI Receptacle, Ivory	GF20IL	2XB84
20A 125V, LED, Faceless GFCI Receptacle, Ivory	GFBF20IL	2XB92
15A 125V, Tamper Resistant GFCI Receptacle, Ivory	GFR5262ITR	1ZPG2
20A 125V, Tamper Resistant GFCI Receptacle, Ivory	GFR5362ITR	1ZPH5
15A 125V, GFCI Plug, Black	GFP5266C	4HD20
15A 125V, GFCI Plug, Yellow	GFP5266CY	4HD21

See Grainger Catalog or Website for Additional Configurations and Colors

Spider Power Distribution Box – Emergency Preparedness

(Page 392 - Catalog 399)

Description	Hubbell #	Grainger#
Military 60A, 3PH 120/208V, (6) 20A 125V Straight Blade Receptacles	SCSB0M2	5LY80
50A, 120/240V, (6) 20A 125V Straight Blade Receptacles	SBSB1	4D577

See Grainger Catalog or Website for Additional Configurations



5LY80




Hubbell Has Your *Electrical Solutions...*




SERVICES OFFERED.....No CHARGE!

Literature (Available Electronically)

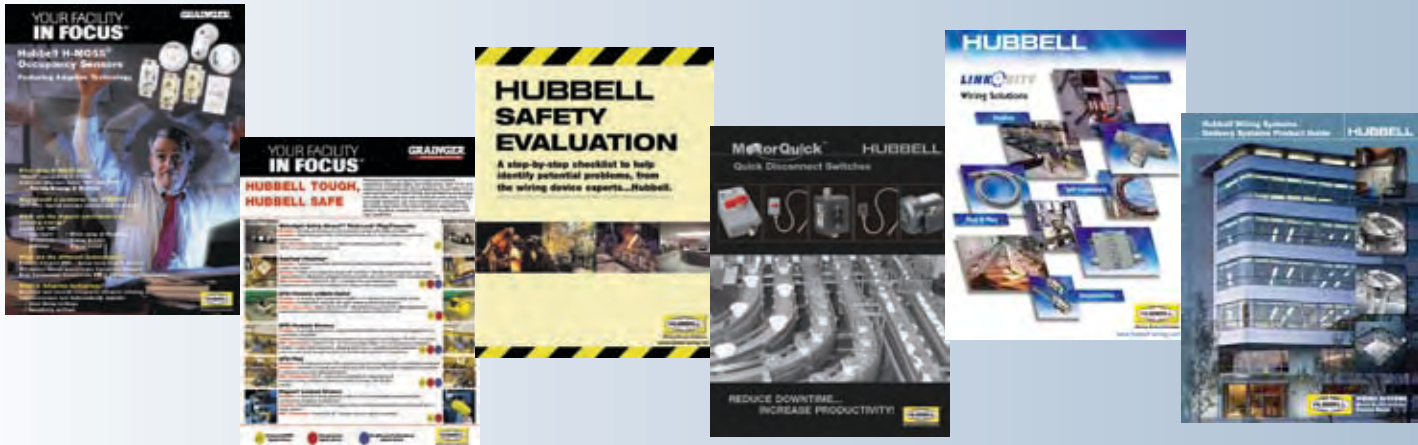

Charts & Selector Guides

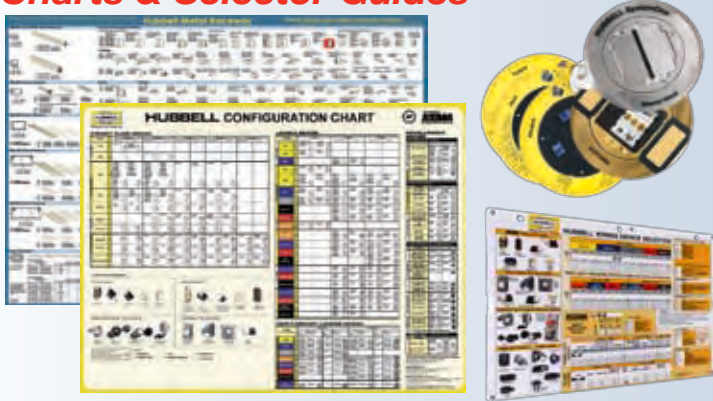

★ *Safety Seminars & Audits*

★ *Energy Audits & Recommendations*

Territory Managers & Contact List

Joint Calls

Product Meetings / Shows

On-site Seminars

Technical Assistance

Competitive Cross References and Comparisons

Shop Talks

Take - Offs

On-line Virtual Catalog and Videos

Electronic Media



Specification Manuals



AVAILABLE THROUGH



8SSP2226