


Tripp Lite Protects the Patient Room Wall to Wall

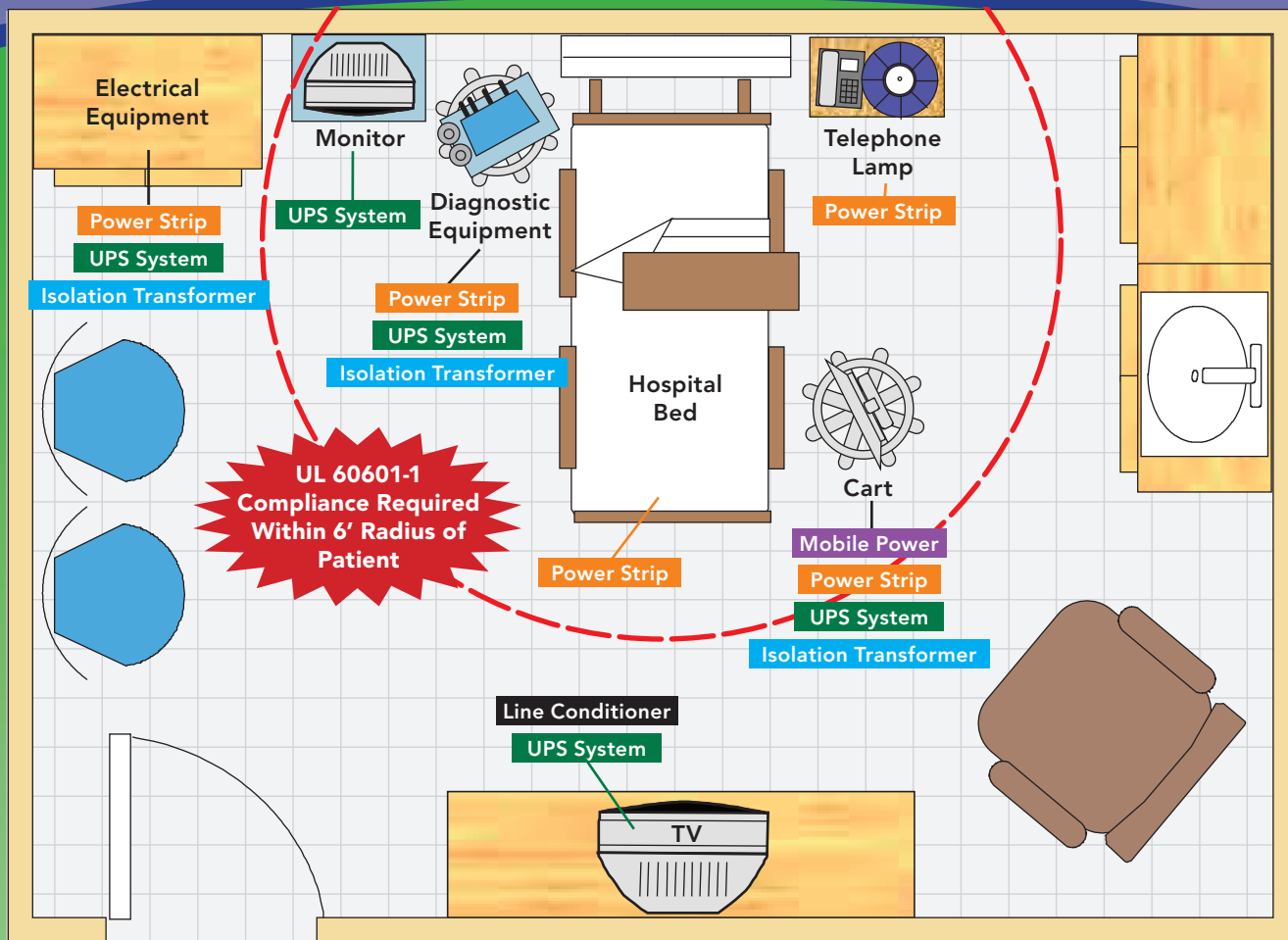

Power Solutions for Every Healthcare Application

UL 60601-1 Medical Grade • Laboratory • IT & Facility • Administration • More



UPS Systems



Isolation Transformers



Outlet Strips



Mobile Power



UL 60601-1 Compliance Made Easy With TRIPP LITE



UPS Systems Medical-Grade

- Meets strict leakage requirements for medical equipment used in nonlife-support applications (UL 60601-1)
- Automatic voltage regulation (AVR) keeps computers working through emergency power checks, low voltage (brownout) and high voltage conditions without using battery power
- Provides portable power to medical staff rolling computer carts to patient rooms
- Mobile retrofit kit No. 2KGF5 adds AC power source to new or existing carts

| Power Rating | | | Back-Up Time Half/Full Load (Min.) | NEMA Plug Configuration | Number of Outlets | Dimensions (In.) | | | Footnotes | Mfr. Model | Item No. |
|--------------|-------|-------|---------------------------------------|----------------------------|----------------------|------------------|-------|------|-----------|----------------|----------|
| VA | Watts | Volts | | | | W | H | D | | | |
| 330 | 225 | 120 | 46/18 | 5-15P HG | 4 | 5.25 | 10.75 | 7.25 | 2,5 | OMNISMART350HG | 3RY95 |
| 750 | 300 | 120 | 12/5 | 5-15P HG | 3 | 6.00 | 11.50 | 3.50 | 3,6 | HCRK | 2KGF5 |
| 700 | 450 | 120 | 42/18 | 5-15P HG | 4 | 7.50 | 12.50 | 9.00 | 2,3,5 | SMART700HG | 5JK37 |
| 1000 | 750 | 120 | 34/16 | 5-15P HG | 4 | 7.50 | 12.50 | 9.00 | 1,2,3,4,5 | SMART1200XLHG | 3RY93 |

(1) Expandable with external battery pack. (2) DB9 serial port. (3) USB communication ports. (4) Includes full featured software with voltage and battery monitoring capability. (5) Hospital-grade plug and receptacles. (6) 10' coiled AC input cord.



Outlet Strips Medical-Grade/Hospital-Grade

- 4 outlet design permits multiple pieces of electrical equipment to operate where outlets and space are limited
- Provides versatile power distribution inside the patient-care area
- Allows for replacement of all non-compliant power strips

| No. of Outlets | Cord Length (Ft.) | Amps | NEMA Plug Configuration | Material of Construction | Description | Dimensions (In.) | | | Mfr. Model | Item No. |
|-------------------|-------------------|------|----------------------------|-----------------------------|-----------------------|------------------|-------|------|----------------|----------|
| | | | | | | L | W | H | | |
| 4 | 15 | 15 | 5-15P HG | Metal | UL60601-1, Switchless | 2.50 | 13.75 | 1.50 | PS-415-HGULTRA | 2GZR4 |



Isolation Transformers Medical-Grade

- Meet UL 60601-1 requirements
- Hospital-grade plug and outlet receptacles
- Full medical-grade listings
- Less than 100 microamps of leakage for connected loads

| VA Rating | Includes | H | Dimensions (In.) | | | Mfr. Model | Item No. |
|-----------|-----------|------|------------------|-------|----------|------------|----------|
| | | | W | D | | | |
| 250 | 2 Outlets | 4.50 | 4.75 | 7.75 | IS250HG | 3RY96 | |
| 500 | 4 Outlets | 5.75 | 6.25 | 9.25 | IS500HG | 3RY97 | |
| 1000 | 4 Outlets | 7.75 | 7.75 | 10.50 | IS1000HG | 3RY98 | |
| 1800 | 6 Outlets | 7.75 | 8.25 | 12.25 | IS1800HG | 1AYB2 | |



www.tripplite.com

For More Information,
Contact Your Grainger Representative.

AVAILABLE THROUGH

