











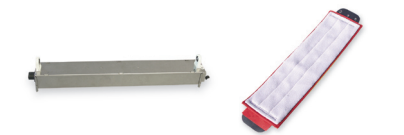






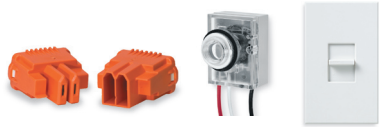


Shining a Spotlight on our Selection of Lighting

CATEGORY	RANGE OF PRODUCTS	BRANDS
Fluorescent Lamps		Circular; Compact: Black Light, Cold Cathode, Germicidal, Plug-In, Spiral; Linear: High Output, T12, T5, T6, T8; Linear Special Application: Gold, Black Light, Plant and Aquarium, Germicidal; U-Shaped
Lamp Accessories		Lamp Changers, Linear Fluorescent Safety Sleeves
Recycling Kits		Batteries; Lamp: CFL, HID, T12, T8, U-Shape; Small Electronics
LED Lamps		Festival, Indicator Lamps, JDR, Miniature, MR11, MR16, PAR16, PAR30
HID Lamps		High Pressure Sodium, Mercury Vapor, Metal Halide
Incandescent Lamps		A19, A15, A21, A23, AR111, BR30, BR40, BT14.5, Decorative, ER30, Halogen Flood, Miniature, MR11, MR16, P25, PAR16, PAR20, PAR30, PAR30L, PAR36, PAR38, PAR46, PAR56, PAR64, PK30d, Projection, PS25, PS30, PS35, PS40, PS52, R14, R16, R20, R40, R52, S6, S11, S14, T2 1/2, T3, T4, T4 1/2, T6, T6 1/2, T7, T8, T10, T14, TB19
LED Light Fixtures		Cove Lighting, Decorative Fixtures, Emergency Light Fixtures, Landscape Flood Lighting, Outdoor Lighting, Retrofit Downlight Trims, Underwater Fixtures
LED Task Lighting		Flat Machine Lights, Gooseneck Task Lights, Machine Tool Lights, Remote Area Lights
Ballasts		Ballast Checker; Circline; Compact Fluorescent; Electronic Fluorescent: Dimming, High Output, Instant-Start, Programmed Start, Rapid Start; HID Core and Coil Kits; Ignitors; Magnetic Fluorescent: High Output, Instant Start, Preheat, Rapid Start, Trigger Start
Lighting Controls		Ballast Disconnects, Dimmer Switches, Lighting Control Panel, Occupancy Sensors, Photocontrols, Remote Control Dimmer System

CATEGORY		RANGE OF PRODUCTS	BRANDS
Indoor Fixtures		HID: High Bay, Low Bay; Fluorescent: Decorative, Hazardous Location, High Bay, Low Bay, Open Channel, Recessed, Rough Service, Surface, T8 Retrofit Kits, Track Lighting, Undercabinet, Vandal-Resistant, Wall Brackets, Wet Location	Appleton, GE, Halo, Hubbell Killark, Lithonia, LumaPro, Metal Optics
Outdoor Fixtures		Floodlights, Motion Sensors, Roadway, Security, Wall Packs	American Electric Lighting, Crescent Stonco, GE, Lithonia, LumaPro
Fixture Accessories		Fluorescent Starters, Lampholders, Light Socket Extenders, Reflectors, Tong Hangers, Wire Guards	GE, Hubbell Wiring Device, Leviton, Lithonia
Ultraviolet Fixtures		Glass View Port, Mounting Rail, Safety Switch, Ultraviolet Fixture	Ultraviolet Devices
Emergency and Exit Lighting		Ceiling Mount Lights, Edge-Lit Exit Signs, Exit Signs, Hazardous Location Lights, Self-Luminous Exit Signs, Vandal-Resistant Exit Signs, Wall-Mount Lights	Isolite, Lithonia
Dock Lights		Fluorescent, Incandescent, Metal Halide, Quartz Halogen	Fostoria, LumaPro
Portable/ Jobsite Lighting		Clamp, Jobsite, Portable, Self-Righting, String, Tripod, Worklights	Fostoria, LumaPro, Luma-Site, Standard Portable, Wobblelight, Woodhead
Task Lighting		Compact Fluorescent Machine Lights, Desk, Drafting, Halogen Machine Lights, Incandescent, Magnifiers, Quartz Halogen	Electrix, Fostoria, LumaPro
Headlamps		Hazardous Location, Incandescent, LED	Energizer, Petzl, Pelican, Rayovac, Streamlight
Flashlights, Lanterns, and Spotlights		Incandescent, LED, Rechargeable, Safety-Approved, Tactical	Brinkmann, Duracell, Energizer, Inova, Pelican, Rayovac, Stanley, Streamlight, Vector, Westward
Batteries		Alkaline, Alkaline Battery Kits, Button / Coin Cell, Carbon Zinc, Hearing Aid, Lithium, Portable Cell Phone Chargers, Rechargeable NiMH, Sealed Lead, Specialty	Duracell, Energizer, Rayovac

For a full listing of lighting products, visit www.grainger.com/lighting

Can't find it? Just ask. Contact us online or by phone—24/7. We make it easy to find the product you need.